




Pass and Seymour  
Discontinued - Hospital Grade Quad Receptacles  
Part No. 420H

Hospital Grade Quad Receptacle 20A 125V

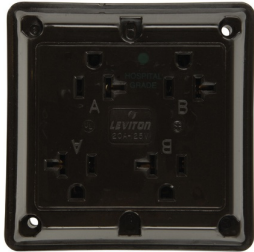

## Features & Benefits

Rugged nylon face and body withstands impacts and hard use.

Built-in wire stripping gauge.

Outward-facing ground terminals make handling up to four straight or angled plugs easy and convenient.

Heavy-duty, phosphor bronze contacts.

Shielding walls guard against live-circuit-to-ground shorts.

Split circuit break-off tabs.

UL and CSA listed.

For covering patents, see [www.legrand.us/patents](http://www.legrand.us/patents).

For compatible wall plate options, from our TradeMaster unbreakable plates to our radiant screwless plates to our metal wall plates, [click here](#).

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Brown
UPC Number	785007496321	Country Of Origin	Mexico
Application Sector	Residential/Commercial	Standard	UL 498, 1449

### Dimensions

Product Width US	4.5 in
------------------	--------

### Listing Agencies / 3rd Party Agencies

CSA Listed	Yes	CSA File Number	16063
------------	-----	-----------------	-------

---

Technical Information

Phase	Three	Number of Wires	3
Amperage	20 A	Number of Poles	Double Pole
Wire Size	14 - 12 AWG	Voltage	125.0 V

---