




Wiremold  
**CabinetMate Plug-In Outlet Center Unit / 120V/20A / 77" long / 12 O/L / 15' cord / Computer Grade Surge**  
 Part No. 7712BDS20R

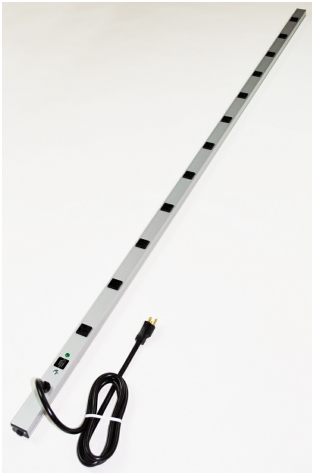

Twelve outlets with t-slots. 15' (4.6m) cord. Length 77" (2m). 20A resettable circuit breaker. Computer grade surge protection, 20 Amps.

## Features & Benefits

Twelve outlets with t-slots. 15' (4.6m) cord. Length 77" (2m). 20A resettable circuit breaker. Computer grade surge protection, 20 Amps.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786776052725
Country Of Origin	Mexico	Application Sector	Residential/Commercial
Standard	cULus Listed: File E66421 Guide XYBS XUHT VZCA	Type	PIOC

### Dimensions

Product Width US	77.0 in	Product Height US	1.19 in
Product Length US	1.5 in		

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E66421	cULus Listed	Yes
---------------------	--------	--------------	-----

### Buy American Act Compliance

NAFTA	Yes
-------	-----

---

## Additional Information

---

RoHS Conformant      Yes

---

## Technical Information

---

Phase                      Single Stage                                      Frequency Rating      +35dB Hz

---

Connection              Cord-ended                                      Class                      75

---

Amperage                      20 A                                      Short Circuit Rating      36000 Amps [12000 Amps L-N  
12000 Amps L-G 12000 Amps N-G]

---

Response Time              <1 ns                                      Mounting Type              Spring Clip

---

Mounting                      Yes                                      Type of Indicators              Light

---

Voltage                      600.0 V

---