




Wiremold  
880MPFC Series Fire Classified Nonmetallic Rectangular Floor Box  
Part No. 880MPFC

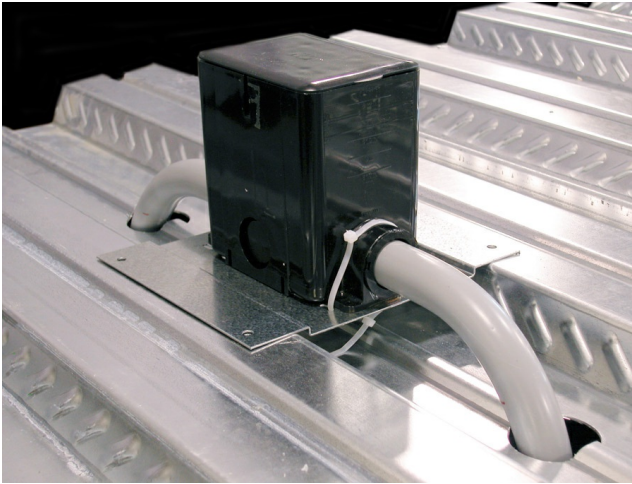

Fire Classified Nonmetallic Rectangular Floor Box. Box comes complete with reusable mudcap, insert spacer, conduit plugs and reducers. Reducers provided for reduction to 1", 3/4", and 1/2" (25mm, 19.1mm, and 12.7mm) conduit. Minimum concrete depth is 3 1/2" (89mm) and maximum concrete depth is 6" (152mm). Minimum capacity is 50 cu. in. (819ml) and maximum capacity is 100 cu. in. (1639ml). Box dimensions are 4 1/8" W x 5 1/2" L x 6" (105mm x 140mm x 152mm). NOTE: Insert spacer should not be removed until after concrete pour. This is a single-gang offering. Cannot gang boxes together and maintain Fire Classification. Floor box spacing 2' on center, no more than 1 per 65 s.f. span. Maximum Copper Cross Section per Insert: Four (4) #12 AWG Type THHN Power Conductor or 48 #23 AWG (6 Cat. 6) Tele Data conductors. Box preserves the 2-hour fire rating of the floor in which it has been installed.

## Features & Benefits

Fire Classified Nonmetallic Rectangular Floor Box. Box comes complete with reusable mudcap, insert spacer, conduit plugs and reducers. Reducers provided for reduction to 1", 3/4", and 1/2" (25mm, 19.1mm, and 12.7mm) conduit. Minimum concrete depth is 3 1/2" (89mm) and maximum concrete depth is 6" (152mm). Minimum capacity is 50 cu. in. (819ml) and maximum capacity is 100 cu. in. (1639ml). Box dimensions are 4 1/8" W x 5 1/2" L x 6" (105mm x 140mm x 152mm). NOTE: Insert spacer should not be removed until after concrete pour. This is a single-gang offering. Cannot gang boxes together and maintain Fire Classification. Floor box spacing 2' on center, no more than 1 per 65 s.f. span. Maximum Copper Cross Section per Insert: Four (4) #12 AWG Type THHN Power Conductor or 48 #23 AWG (6 Cat. 6) Tele Data conductors. Box preserves the 2-hour fire rating of the floor in which it has been installed.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786564072119
Country Of Origin	United States	Construction	Assembled
Number of Knockouts	2	Application Sector	Commercial
Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.	Type	Floor Box

### Dimensions

Cubic Capacity	50 cu in
----------------	----------

---

## Listing Agencies / 3rd Party Agencies

---

cULus ListingNumber	E110748	cULus Listed	Yes
---------------------	---------	--------------	-----

---

## Additional Information

---

RoHS Conformant	Yes
-----------------	-----

---

## Technical Information

---

Cable Entry	CONDUIT
-------------	---------

---