




adore Collection
Discontinued - adore® Control Box with Paddle™ Dimmer and 15A GFCI Outlet, White
Part No. APCB6W2

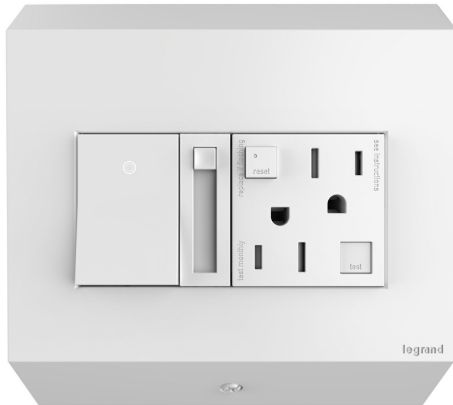

Add precise lighting control and power access, complete with self-testing GFCI protection, to your adore Under-Cabinet solution. This lighting control box includes a Paddle Dimmer as well as a 15A GFCI Outlet, and connects easily to existing in-wall wiring for clean counters and more functional space.

Features & Benefits

- Perfect for eliminating clutter and creating a more functional kitchen counter space

Connects to existing in-wall wiring to power your Under-Cabinet Lighting and Power System

Single-pole operation is ideal for controlling a garbage disposal or adore LED Linear Lights

Once installed, this item is designed to fit onto the adore Modular Track
- Keeps countertops free of the hazards and mess of wires

Includes an adore Paddle Dimmer and self-testing GFCI Outlet

Designed for professional, hard-wired installations

Specifications

General Info

| | | | |
|-----------------------|----------------|--------------------|-------------------------------------|
| Product Line | Pass & Seymour | Color | White |
| Finish | Matte | Country Of Origin | China |
| Number of Receptacles | 2 | Features | Dimmable |
| Switch Type | Paddle | Number of Switches | 1 |
| Outlet Type | GFCI | Package Quantity | 1 |
| Application Sector | Residential | Type | Combination, Dimmer, Outlet, Switch |

Technical Information

| | | | |
|---------------------|----|----------|--------|
| Is Tamper-Resistant | No | Actuator | Paddle |
|---------------------|----|----------|--------|

| | | | |
|--------------------------|-----------------------------------------|--------------------|--------|
| Amperage | 15 A | Bulb Compatibility | LED |
| Is Weather Resistant | No | Indoor/Outdoor | Indoor |
| Wattage | 450 W | Supply Voltage | 120 V |
| Voltage | 125.0 V | Connection Type | Wired |
| Environmental Conditions | 95% (relative humidity, non-condensing) | | |