




adorne Collection  
Discontinued - adorne®15A Wi-Fi Ready Outlet, Magnesium  
Part No. ARPS15RF2M4

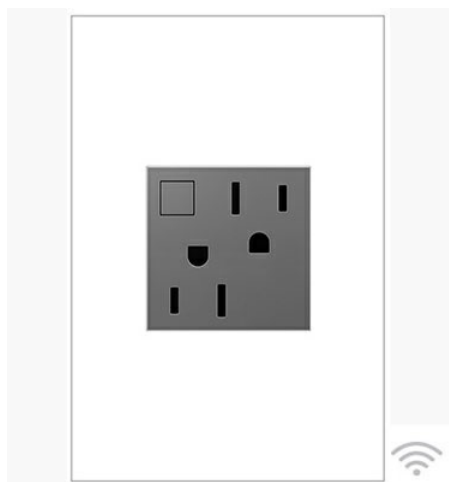

## Features & Benefits

Installs in 15 minutes or less, fitting into an existing electrical box. No new wiring required for typical installation.

Pairs with the Wi-Fi Ready Remote Switch for multi-location control of a plugged in lamp or small appliance.

Part of the adorne Wi-Fi Lighting Control solution, this product requires an adorne Hub.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Complete the look with a stunning, screwless adorne® Wall Plate, not included. Available in a range of contemporary colors and finishes. Coordinate with other designer switches & outlets.

## Specifications

### General Info

|                       |                                  |                   |   |
|-----------------------|----------------------------------|-------------------|---|
| Product Line          | Pass & Seymour                   | Color             | Magnesium                                       |
| Finish                | Frosted                          | Country Of Origin | China   |
| Number of Receptacles | 2                                | Works With        | Amazon Alexa, Google Assistant, Radio Frequency |
| Outlet Type           | Indoor, Residential, Wi-Fi Ready | Warranty Type     | Limited Lifetime Warranty                       |
| Type                  | Outlet                           |                   |   |

### Technical Information

|                 |   |          |      |
|-----------------|---|----------|------|
| Number of Gangs | 1 | Amperage | 15 A |
|-----------------|---|----------|------|

|                 |                          |                          |   |
|-----------------|--------------------------|--------------------------|---|
| Indoor/Outdoor  | Indoor                   | NEMA Configuration Code  | 5-15R                                   |
| Mounting Type   | Box                      | Voltage                  | 125 V                                   |
| Connection Type | Internal Pressure Plates | Environmental Conditions | 95% (relative humidity, non-condensing) |