




On-Q  
42-inch Enclosure, No Cover  
Part No. EN4280

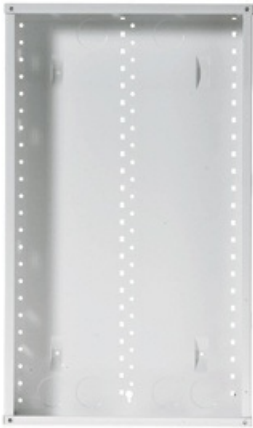

Perfect for larger installations, this 42" enclosure features universal On-Q style mounting holes that are compatible with all bay-style modules. It also includes larger top openings that make pulling wire easier as well as additional knockouts, more s

## Features & Benefits

Includes five openings on the top of the enclosure with knockouts

Drywall depth indicators

Flush and surface installation

Mounting tabs provide correct flush-mount position for standard installations

Patented mounting system offers versatile module mounting options

Literature pouch included for dealer information

Includes self-adhesive cable identification table

Made in the USA

## Specifications

### General Info

|                  |                                              |                    |               |
|------------------|----------------------------------------------|--------------------|---------------|
| Product Line     | On-Q                                         | Color              | White         |
| UPC Number       | 804428023203                                 | Country Of Origin  | United States |
| Package Quantity | 1                                            | Application Sector | Residential   |
| Standard         | UL (UL985, UL1023, UL1863), cULus, CSA, RoHS | Type               | Enclosure     |

### Dimensions

|                   |          |                  |        |
|-------------------|----------|------------------|--------|
| Product Width US  | 14.25 in | Product Depth US | 3.6 in |
| Product Height US | 42.0 in  |                  |        |

### Listing Agencies / 3rd Party Agencies

|            |     |              |     |
|------------|-----|--------------|-----|
| CSA Listed | Yes | cULus Listed | Yes |
|------------|-----|--------------|-----|

Additional Information

|                 |     |
|-----------------|-----|
| RoHS Conformant | Yes |
|-----------------|-----|

Technical Information

|             |                                                                                            |                |                   |
|-------------|--------------------------------------------------------------------------------------------|----------------|-------------------|
| Thickness   | 0.1 in                                                                                     | Enclosure Type | Traditional       |
| Cable Entry | (6) rear knockouts, (3) top knockouts, (2) rectangular knockouts for 1-gang electrical box | Frame          | Cold Rolled Steel |