




Pass and Seymour
Discontinued - Stainless Steel Support Grips Standard Duty, Closed Mesh
Part No. FC175USS

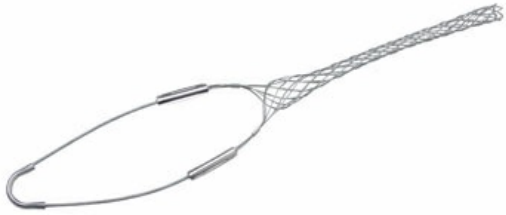

Stainless Steel, Standard-duty, Closed mesh, Single eye grips. Cable Diameter - 1.750-1.990", Bale length - 14", Mesh length - 20", Break strength - 2,640 lbs.

Features & Benefits

Standard duty closed mesh support grips are designed for loads up to 600 lbs.

Vertical runs of no more than 100 ft.

They are available in a variety of eye styles and cable ranges for supporting electrical and fiber optic cable, metal rods, and tubing.

Closed mesh support grips are used when the end of the cable is accessible.

Support grips are woven of corrosion-resistant stainless steel wire.

Most Flexcor products have UL and/or CSA approvals. Please contact factory for approval information.

Specifications

General Info

| | | | |
|-------------------|----------------|-------------------------|--------|
| Product Line | Pass & Seymour | Replaced by Part Number | FC175U |
| Country Of Origin | Mexico | | |

Listing Agencies / 3rd Party Agencies

| | | | |
|------------|-----|-----------------|----|
| CSA Listed | Yes | CSA File Number | NO |
|------------|-----|-----------------|----|