


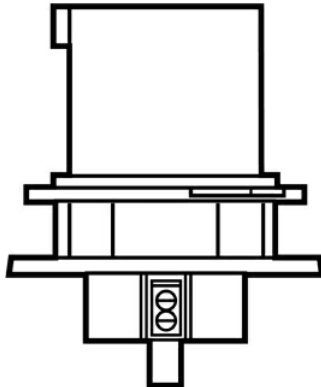

Pass and Seymour  
Pin & Sleeve **Splashproof 20A 3øY 277V/480V Inlet**  
Part No. PS520B7S

4-Pole, 5-Wire, Pin and Sleeve Inlet. 20A, 3Y, 277/480V.



## Features & Benefits

All P&S Watertight Pin & Sleeve plugs, connectors, receptacles, and inlets bring you the features to enhance versatility, reliability, and safety.

And all feature chemical-resistant thermoplastic construction.

An exclusive, hinged cord grip eliminates loose parts that get lost.

North American products come completely ready to wire, for quick, simple installation.

Shrouded, nickel-plated, solid-brass pins provide corrosion protection and excellent conductivity.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Gray
Country Of Origin	United States	Application Sector	Industrial
Standard	UL Listed		

### Dimensions

Product Width US	3.7 in	Product Height US	3.7 in
Product Length US	3.39 in		

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	151348	cULus Listed	Yes
---------------------	--------	--------------	-----

### Technical Information

Number of Wires	5	Amperage	20 A
Number of Poles	4-Way	Voltage	277.0 V